


E12463



Soket berkabel

SDOGF030MSSFKPG

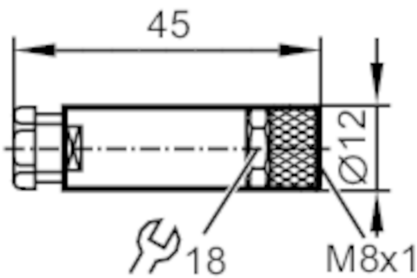

Aplikasi		
Fitur khusus		Kontak berlapis emas
Data kelistrikan		
Tegangan pengoperasian	[V]	< 30 AC/DC
Output		
Desain kelistrikan		PNP
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67
Data teknis		
Berat	[g]	10.7
Dimensi	[mm]	12 x 12 x 45
Material		PBT; PA
Material bodi detakan		PBT / PA
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah

E12463



Soket berkabel

SDOGF030MSSFKPG

Koneksi listrik

terminal sekrup: 0.14...0.5 mm²; Selubung kabel: Ø 3.5...5 mm

Koneksi listrik - soket

Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: PBT / PA; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas



Koneksi

