


## Splitter Y

ZDO2H050MSS0000-00STGH050MSS

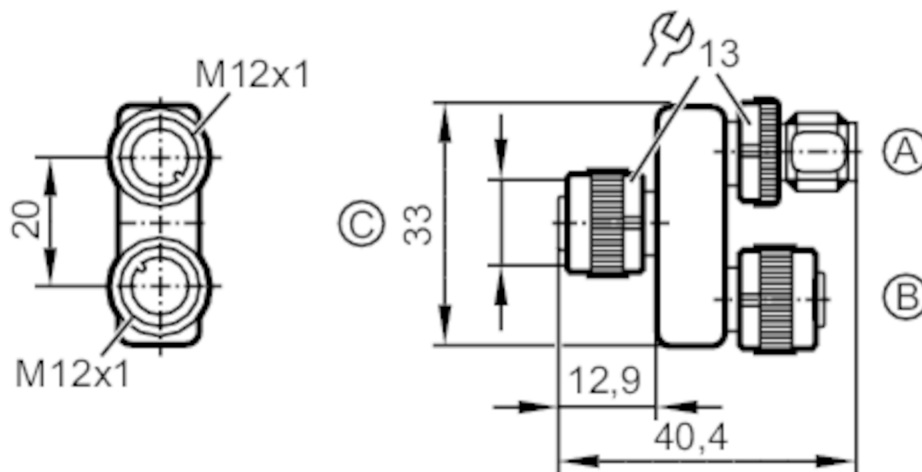

## Aplikasi

|                    |                                          |
|--------------------|------------------------------------------|
| Fitur khusus       | Bebas dari silikon; Kontak berlapis emas |
| Bebas dari silikon | ya                                       |

## Data kelistrikan

|                                 |     |         |
|---------------------------------|-----|---------|
| Tegangan pengoperasian          | [V] | < 60 DC |
| Beban arus maks. per modul/slot | [A] | 4       |
| Total beban arus maks.          | [A] | 4       |

## Kondisi pengoperasian

|              |      |          |
|--------------|------|----------|
| Suhu sekitar | [°C] | -25...85 |
| Perlindungan |      | IP 67    |

## Data teknis

|                       |     |            |
|-----------------------|-----|------------|
| Berat                 | [g] | 23.9       |
| Material              |     | PUR        |
| Material bodi detakan |     | PUR        |
| Material mur          |     | seng tuang |
| Tipe konektor         |     | M12        |

## Keterangan

|              |        |
|--------------|--------|
| Jumlah paket | 1 buah |
|--------------|--------|




### Splitter Y


ZDO2H050MSS0000-00STGH050MSS

## Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang; Kontak: dilapisi emas

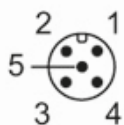

## Koneksi

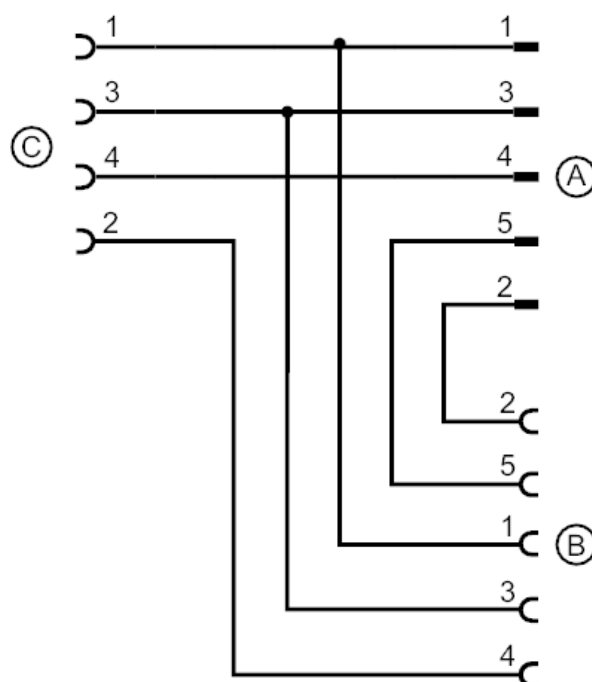

## Koneksi listrik - soket

Konektor: 2 x M12; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang; Kontak: dilapisi emas

