


E12492



Kabel koneksi Ethernet

VSTGN040ZDS0010L04STGP040--S

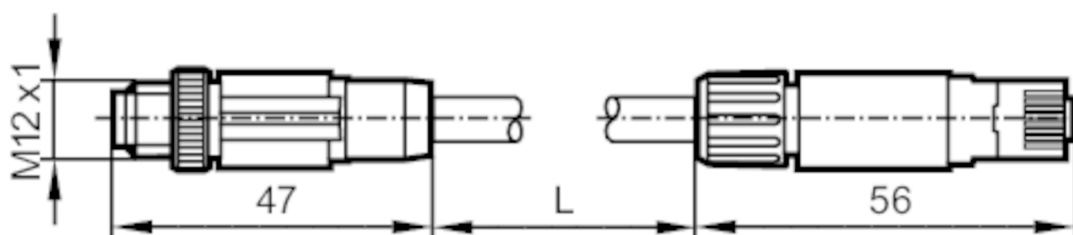

Aplikasi

Fitur khusus	Kabel berpelindung
Desain	Kabel Ethernet, Dengan kode D
Aplikasi	kabel patch silang; kabel patch

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...70
Perlindungan	IP 67; IP 20; (Colokan M12/colokan RJ45)	

Data teknis

Berat	[g]	702.5
Material	TPU / PA	
Material bodi detakan	PA / TPU	
Material mur	seng tuang, berlapis nikel	

Keterangan

Jumlah paket	1 buah
--------------	--------

Kabel koneksi Ethernet

VSTGN040ZDS0010L04STGP040--S

Koneksi listrik - colokan M12


Konektor: 1 x M12, lurus; pengkodean: D; Bodi cetakan: PA; Penguncian: seng tuang, berlapis nikel; Torsi pengencangan: 0.7...0.9 Nm



Koneksi listrik

Kabel: 10 m, PVC, hijau, Ø 6.5 mm, berpelindung; 2 x 2 x 0.38 mm²

Koneksi

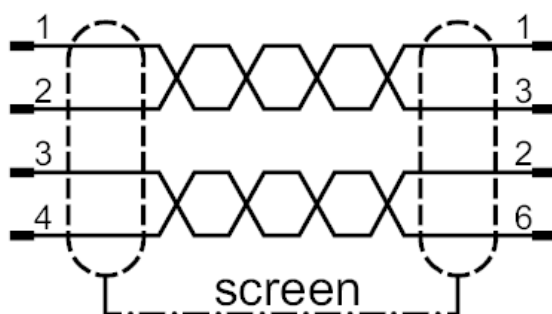

Koneksi listrik - colokan RJ45

Konektor: 1 x RJ45, lurus; Bodi cetakan: TPU

