


Kabel koneksi dengan soket

ADOGD040ZDS00,5H04

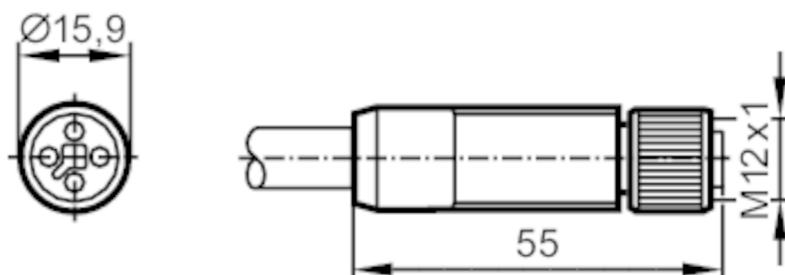

Aplikasi		
Fitur khusus		Kontak berlapis emas
Desain		kabel daya, Dengan kode T
Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 DC
Total beban arus maks.	[A]	12
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67
Data teknis		
Berat	[g]	84.8
Dimensi	[mm]	15.4 x 15.4 x 52.8
Material		PP
Material bodi detakan		TPU
Material mur		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah

E12494



Kabel koneksi dengan soket


ADOGD040ZDS00,5H04

Koneksi listrik

Kabel: 0.5 m, PUR, hitam, Ø 8 mm; 4 x 1.5 mm²

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: T; Bodi cetakan: TPU; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas

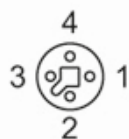

Koneksi



BK =
BN =
BU =
WH =

Warna core :
hitam
coklat
biru
putih