

E12497



Kabel koneksi dengan soket

ADOGD040ZDS0020H04



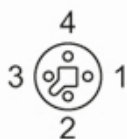
Aplikasi		
Fitur khusus		Kontak berlapis emas
Desain		kabel daya, Dengan kode T
Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 DC
Total beban arus maks.	[A]	12
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67
Data teknis		
Berat	[g]	2053.5
Dimensi	[mm]	15.4 x 15.4 x 52.8
Material		PP
Material bodi detakan		TPU
Material mur		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah

**Kabel koneksi dengan soket**

ADOGD040ZDS0020H04

Koneksi listrikKabel: 20 m, PUR, hitam, Ø 8 mm; 4 x 1.5 mm²**Koneksi listrik - soket**

Konektor: 1 x M12, lurus; pengkodean: T; Bodi cetakan: TPU; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas

**Koneksi**

BK =	Warna core :
BN =	hitam
BU =	coklat
WH =	biru
	putih