


Kabel koneksi

VDOGH040MSS0007H04STGH04MSS

spesifik pelanggan

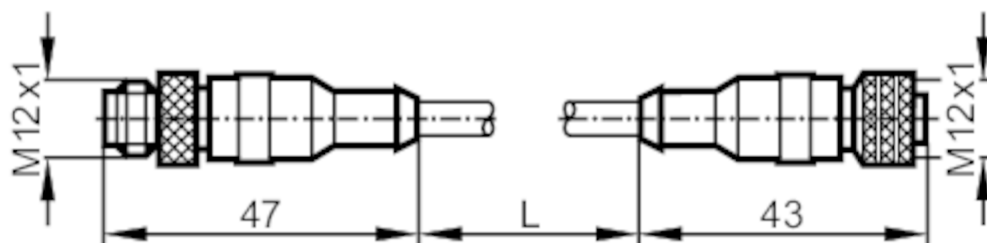

Aplikasi

Fitur khusus	Kesesuaian rantai tarik
Aplikasi	tahan terhadap mikroba
Tahan oli	ya
Tahan UV	ya

Data kelistrikan

Tegangan pengoperasian [V]	< 250 AC / < 300 DC
Kelas perlindungan	II
Total beban arus maks. [A]	4

Kondisi pengoperasian

Suhu sekitar [°C]	-40...90
Suhu sekitar (bergerak) [°C]	-15...70
Perlindungan	IP 65; IP 67

Data teknis

Berat [g]	309.5
Material	casing: TPE-U hitam; Segel: FKM
Material mur	seng tuang, berlapis nikel
Kesesuaian rantai tarik	ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel
	min. 8 x diameter kabel
	radius pembengkokan untuk pemasangan tetap
	min. 4 x diameter kabel

Keterangan

Keterangan	tahan terhadap tekanan mekanis yang tinggi
------------	--


**Kabel koneksi**

VDOGH040MSS0007H04STGH04MSS

Catatan	spesifik pelanggan
Jumlah paket	1 buah

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Penguncian: seng tuang, berlapis nikel; Torsi pengencangan: 0.7...0.9 Nm

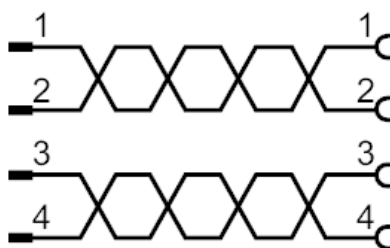**Koneksi listrik**Kabel: 7 m, PUR, hitam, Ø 5.8 mm; pasangan terpilin; 2 x 0.34 mm² (42 x Ø 0.1 mm)**Koneksi****Koneksi listrik - soket**

Konektor: 1 x M12, lurus; pengkodean: A; Penguncian: seng tuang, berlapis nikel; Torsi pengencangan: 0.7...0.9 Nm

