


E12554



Kabel koneksi Y

YDOGS040PLS0005H02

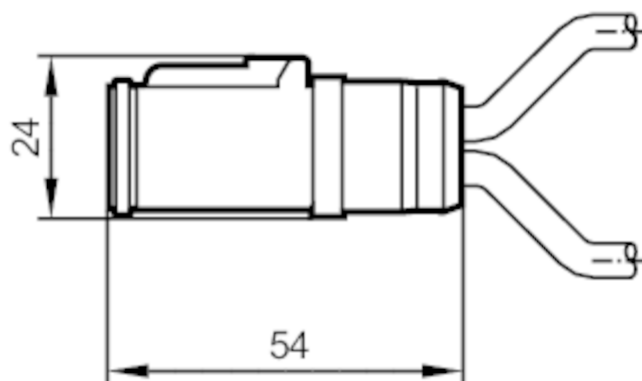

Aplikasi

Fitur khusus	Bebas dari silikon; Bebas halogen; Kesesuaian rantai tarik
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian [V]	8...32 DC
Kelas perlindungan	III
Total beban arus maks. [A]	4

Kondisi pengoperasian

Suhu sekitar [°C]	-40...85
Suhu sekitar (bergerak) [°C]	-20...85
Perlindungan	IP 67; (pasangan konektor terpasang)

Data teknis

Berat	[g]	346.8	
Dimensi	[mm]	24 x 24 x 54	
Material		PA	
Jumlah port kotak splitter		2	
Kesesuaian rantai tarik		ya	
Kesesuaian rantai tarik		radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
		kecepatan pergerakan	maks. 3,3 m/dtk untuk panjang pergerakan horizontal 5 m dan akselerasi maks. 5 m/dtk²
		siklus pembengkokan	> 5 Mio.
		ketegangan torsional	± 180 °/m

E12554



Kabel koneksi Y

YDOGS040PLS0005H02

Keterangan

Jumlah paket

1 buah

Koneksi listrik


Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 5.4 mm; 2 x 0.50 mm² (28 x Ø 0.15 mm)

Koneksi listrik - soket

Konektor: 1 x Konektor DEUTSCH, lurus; Kontak: berlapis nikel



Koneksi

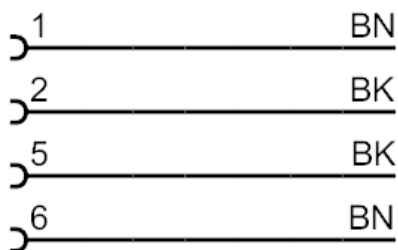

BK =
BN =

Warna core :
hitam
coklat