


E12566



Kabel koneksi dengan konektor AMP

ADOGX060--A005E06

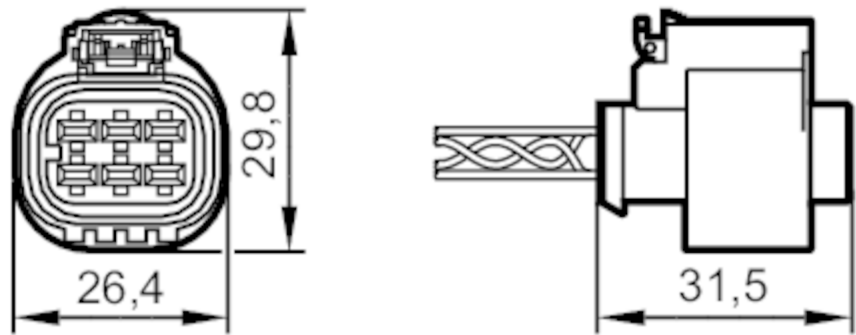

Data kelistrikan		
Tegangan pengoperasian	[V]	12...24 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...100
Suhu sekitar (bergerak)	[°C]	-40...100
Perlindungan		IP 67; (pasangan konektor terpasang)
Data teknis		
Berat	[g]	576.5
Material		PBT
Keterangan		
Jumlah paket		1 buah

E12566



Kabel koneksi dengan konektor AMP


ADOGX060--A005E06

Koneksi listrik

Kabel: 5 m, PVC; 4 x 2.5 mm² + 2 x 0.5 mm²

Koneksi listrik - soket

Koneksi

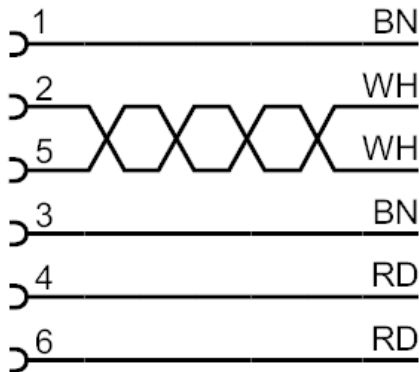

BN =
RD =
WH =

Warna core :
coklat
merah
putih

Konektor: 1 x Konektor AMP, lurus; Kontak: berlapis nikel