




Soket AMP berkabel

SDOGV060--AFKCR

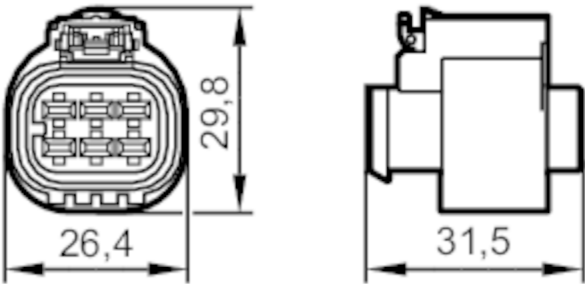

Data kelistrikan		
Tegangan pengoperasian	[V]	12...24 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...100
Suhu sekitar (bergerak)	[°C]	-40...100
Perlindungan		IP 67; (pasangan konektor terpasang)
Data teknis		
Berat	[g]	14
Dimensi	[mm]	29.8 x 26.4 x 31.5
Material		casing soket: PBT; Kontak: dilapisi timah
Aksesori		
Item dikirim		colokan penutup: 6
		penyegelan masing-masing core: 2 x 0,5 mm²
		penyegelan masing-masing core: 4 x 2,5 mm²
		Kontak Crimp: 6
Koneksi listrik		
terminal: 2 x 0.5 mm²		

E12582




Soket AMP berkabel

SDOGV060--AFKCR

4 x 2.5 mm²

Koneksi listrik - soket

Koneksi

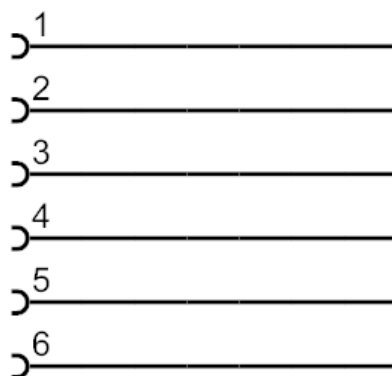

Konektor: 1 x Konektor AMP, lurus; Kontak: dilapisi timah