


E12644



Kabel koneksi dengan soket

ADOGX050MSS0020H05

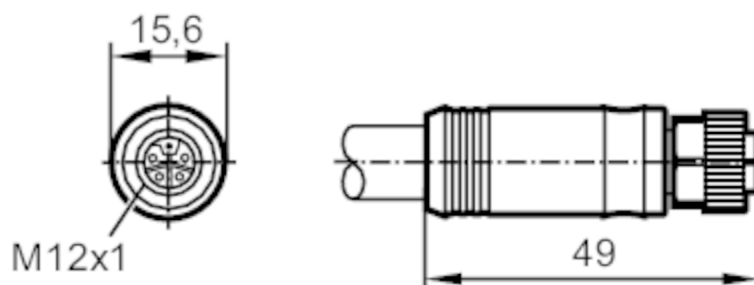

Aplikasi

Fitur khusus	Kontak berlapis emas
Desain	kabel daya, Dengan kode L

Data kelistrikan

Tegangan pengoperasian	[V]	63 DC
Total beban arus maks.	[A]	16

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...90
Perlindungan		IP 67

Data teknis

Berat	[g]	4315.5
Dimensi	[mm]	49 x 15.6 x 15.6
Material		PP
Material bodi detakan		TPE
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------

E12644



Kabel koneksi dengan soket

ADOGX050MSS0020H05

Koneksi listrik

Kabel: 20 m, PUR, hitam, Ø 11.3 mm; 5 x 2.5 mm²

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: L; Bodi cetakan: TPE; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas



Koneksi

1	BN
2	WH
3	BU
4	BK
5	GY