


E12649



Kabel koneksi dengan soket

ADOAX050MSS0020H05

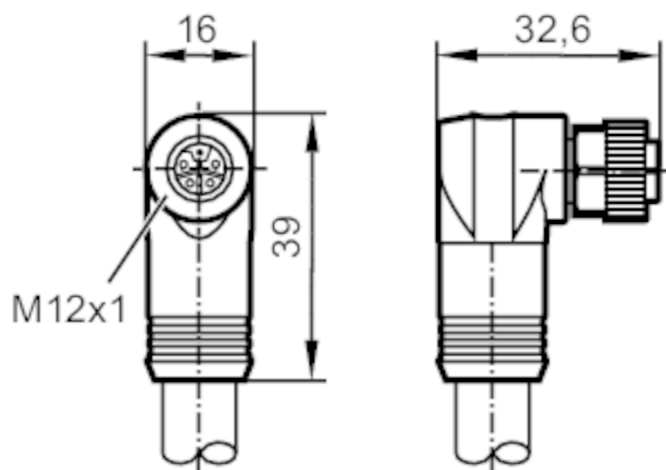

Aplikasi		
Fitur khusus		Kontak berlapis emas
Desain		kabel daya, Dengan kode L
Data kelistrikan		
Tegangan pengoperasian	[V]	63 DC
Total beban arus maks.	[A]	16
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...90
Perlindungan		IP 67
Data teknis		
Berat	[g]	4143.9
Dimensi	[mm]	39 x 16 x 38.1
Material		PP
Material bodi detakan		TPE
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah

E12649



Kabel koneksi dengan soket

ADOAX050MSS0020H05

Koneksi listrik

Kabel: 20 m, PUR, hitam, Ø 11.3 mm; 5 x 2.5 mm²

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: L; Bodi cetakan: TPE; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas



Koneksi

1	BN
2	WH
3	BU
4	BK
5	GY