


E12656



Kabel koneksi

VDOGX050MSS0010H05STGH005MSS

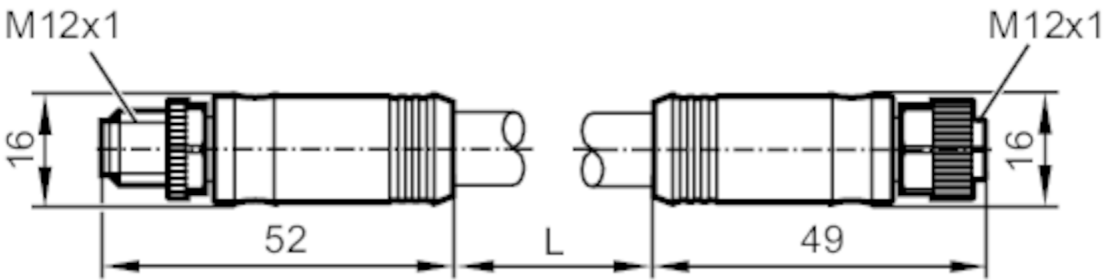

Aplikasi		
Fitur khusus		Kontak berlapis emas
Desain		kabel daya, Dengan kode L
Data kelistrikan		
Tegangan pengoperasian	[V]	64 DC
Total beban arus maks.	[A]	16
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...90
Perlindungan		IP 67
Data teknis		
Berat	[g]	2165.2
Material		PP
Material bodi detakan		TPE
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah

Kabel koneksi

VDOGX050MSS0010H05STGH005MSS

Koneksi listrikKabel: 10.0 m, PUR, hitam, Ø 11.3 mm; 5 x 2.5 mm²**Koneksi listrik - colokan**

Konektor: 1 x M12, lurus; pengkodean: L; Bodi cetakan: TPE; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

**Koneksi listrik - 2**

Koneksi

**Koneksi listrik - soket**

Konektor: 1 x M12, lurus; pengkodean: L; Bodi cetakan: TPE; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

