


Kabel koneksi

VDOAX050MSS00,5H05STGH005MSS

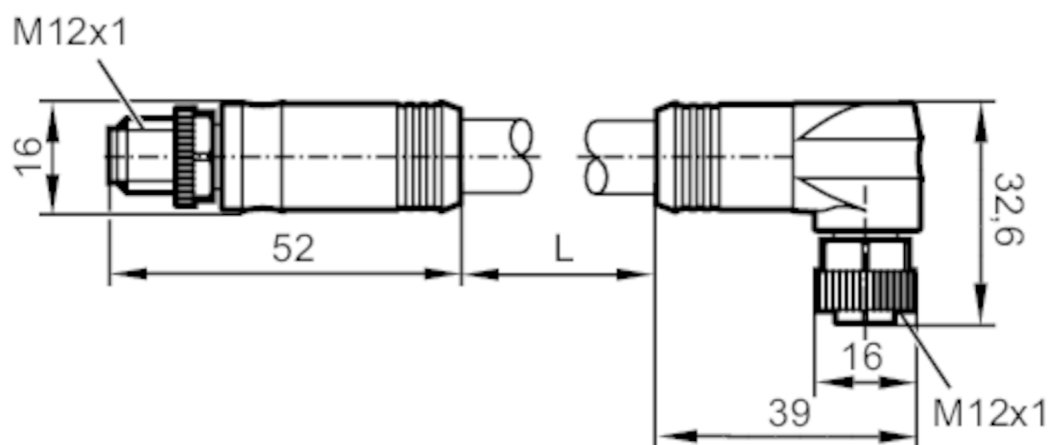

Aplikasi

Fitur khusus

Kontak berlapis emas

Desain

kabel daya, Dengan kode L

Data kelistrikan

Tegangan pengoperasian

[V]

64 DC

Total beban arus maks.

[A]

16

Kondisi pengoperasian

Suhu sekitar

[°C]

-40...90

Perlindungan

IP 67

Data teknis

Berat

[g]

151.9

Material

PP

Material bodi detakan

TPE

Material mur

kuningan, berlapis nikel

Keterangan

Jumlah paket

1 buah

**Kabel koneksi**


VDOAX050MSS00,5H05STGH005MSS

Koneksi listrikKabel: 0.5 m, PUR, hitam, Ø 11.3 mm; 5 x 2.5 mm²**Koneksi listrik - colokan**

Konektor: 1 x M12, lurus; pengkodean: L; Bodi cetakan: TPE; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

**Koneksi listrik - 2**

Koneksi

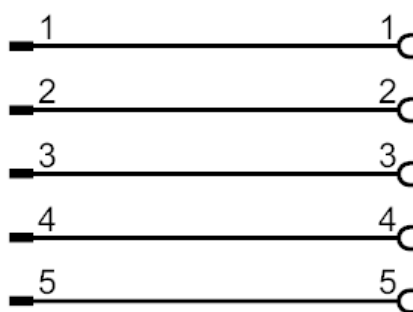**Koneksi listrik - soket**

Konektor: 1 x M12, bersiku; pengkodean: L; Bodi cetakan: TPE; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

