


E12660



Kabel koneksi

VDOAX050MSS0001H05STGH005MSS

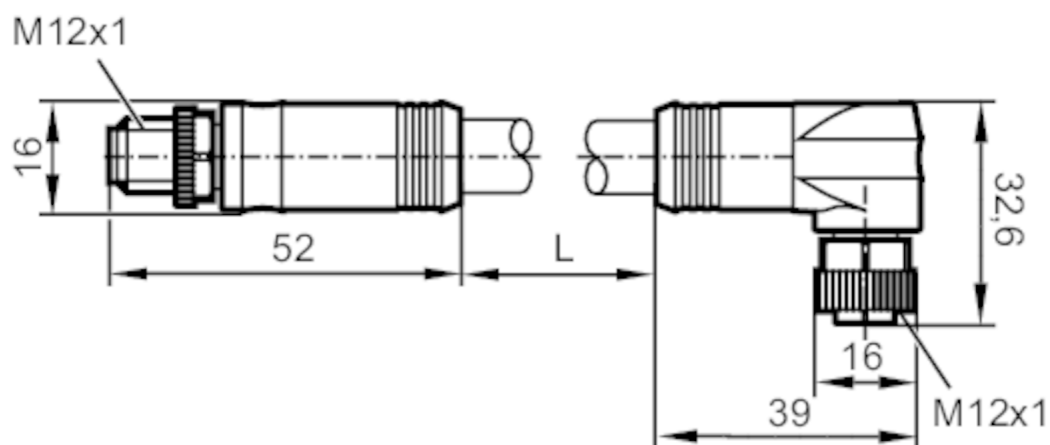

Aplikasi

Fitur khusus	Kontak berlapis emas
Desain	kabel daya, Dengan kode L

Data kelistrikan

Tegangan pengoperasian	[V]	64 DC
Total beban arus maks.	[A]	16

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...90
Perlindungan		IP 67

Data teknis

Berat	[g]	257.2
Material		PP
Material bodi detakan		TPE
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------

**Kabel koneksi**

VDOAX050MSS0001H05STGH005MSS

Koneksi listrikKabel: 1.0 m, PUR, hitam, Ø 11.3 mm; 5 x 2.5 mm²**Koneksi listrik - colokan**

Konektor: 1 x M12, lurus; pengkodean: L; Bodi cetakan: TPE; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

**Koneksi listrik - 2**

Koneksi

**Koneksi listrik - soket**

Konektor: 1 x M12, bersiku; pengkodean: L; Bodi cetakan: TPE; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

