


E12665



Kabel koneksi

VDOAX050MSS0,25H05STAH005MSS

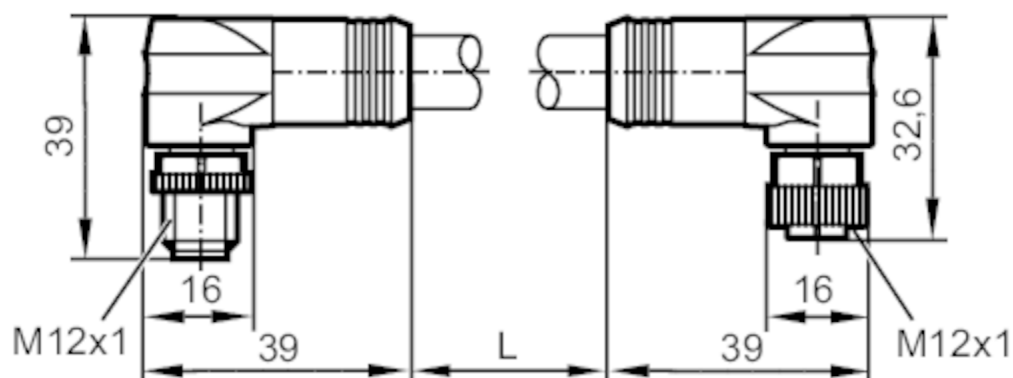

Aplikasi

Fitur khusus	Kontak berlapis emas
Desain	kabel daya, Dengan kode L

Data kelistrikan

Tegangan pengoperasian	[V]	64 DC
Total beban arus maks.	[A]	16

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...90
Perlindungan		IP 67

Data teknis

Berat	[g]	103.1
Material		PP
Material bodi detakan		TPE
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------



Kabel koneksi

VDOAX050MSS0,25H05STAH005MSS

Koneksi listrik

Kabel: 0.25 m, PUR, hitam, Ø 11.3 mm; 5 x 2.5 mm²

Koneksi listrik - colokan

Konektor: 1 x M12, bersiku; pengkodean: L; Bodi cetakan: TPE; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas



Koneksi listrik - 2

Koneksi



Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: L; Bodi cetakan: TPE; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

