


Soket berkabel

SDOGX050ZDSFKPG

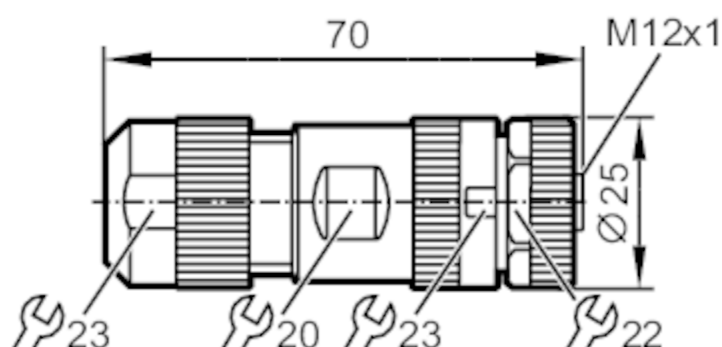

Aplikasi

Fitur khusus	Kontak berlapis emas
Desain	Dengan kode L

Data kelistrikan

Tegangan pengoperasian	[V]	< 63 DC
Total beban arus maks.	[A]	16

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67

Data teknis

Berat	[g]	53.2
Dimensi	[mm]	20 x 20 x 58
Material		PA
Material bodi detakan		PA
Material mur		seng tuang, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------

E12672



Soket berkabel

SDOGX050ZDSFKPG

Koneksi listrik

terminal sekrup: 1.5...2.5 mm²; Selubung kabel: Ø 8...13 mm; maks. 1.5 dengan pengikat ujung kabel

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: L; Bodi cetakan: PA; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas



Koneksi

