


E12673



Colokan berkabel

SSTGX050ZDSFKPG

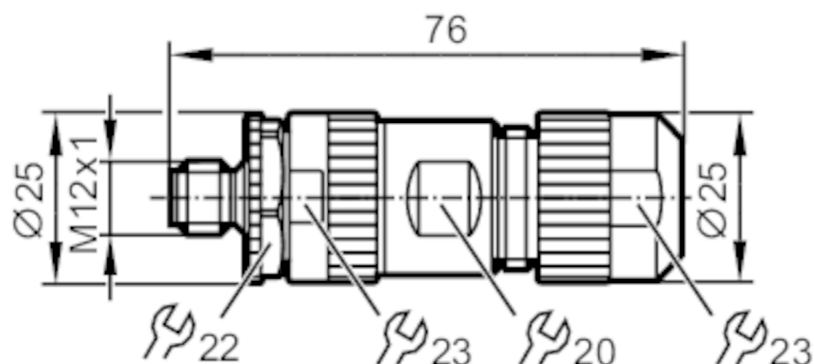

Aplikasi

Fitur khusus	Kontak berlapis emas
Desain	Dengan kode L

Data kelistrikan

Tegangan pengoperasian	[V]	< 63 DC
Total beban arus maks.	[A]	16

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67

Data teknis

Berat	[g]	43.05
Dimensi	[mm]	Ø 25 / L = 76
Material		PA
Material bodi detakan		PA
Material mur		seng tuang, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E12673



Colokan berkabel

SSTGX050ZDSFKPG

Koneksi listrik

terminal sekrup: 1.5...2.5 mm²; Selubung kabel: Ø 8...13 mm

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: L; Bodi cetakan: PA; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas



Koneksi

