


E12684



Kabel koneksi Y

YDOGS060--S0005H03DOGH030MSS

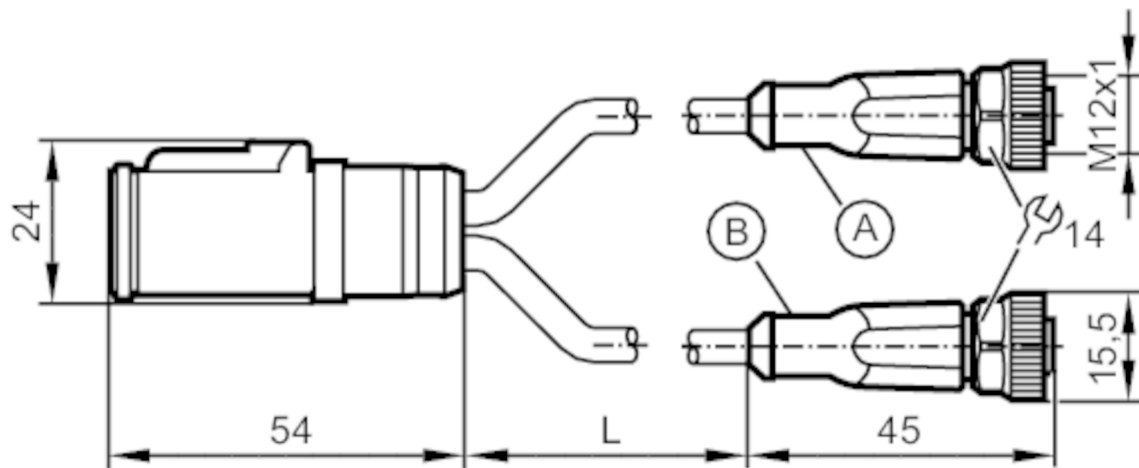


Aplikasi		
Fitur khusus	Bebas dari silikon; Bebas halogen; Kesesuaian rantai tarik	
Bebas dari silikon	ya	
Data kelistrikan		
Tegangan pengoperasian	[V]	8...32 DC
Kelas perlindungan		III
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...80
Suhu sekitar (bergerak)	[°C]	-20...80
Perlindungan		IP 67; (pasangan konektor terpasang)
Data teknis		
Berat	[g]	405.214
Material	PA; soket: TPU oranye; Segel: FKM	
Material mur	kuningan, berlapis nikel	
Jumlah port kotak splitter	2	
Kesesuaian rantai tarik	ya	
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	kecepatan pergerakan	maks. 3,3 m/dtk untuk panjang pergerakan horizontal 5 m dan akselerasi maks. 5 m/dtk²
	siklus pembengkokan	> 5 Mio.
	ketegangan torsional	± 180 °/m
Keterangan		
Jumlah paket	1 buah	

Kabel koneksi Y

YDOGS060--S0005H03DOGH030MSS

Koneksi listrik - Konektor DEUTSCH C

Koneksi

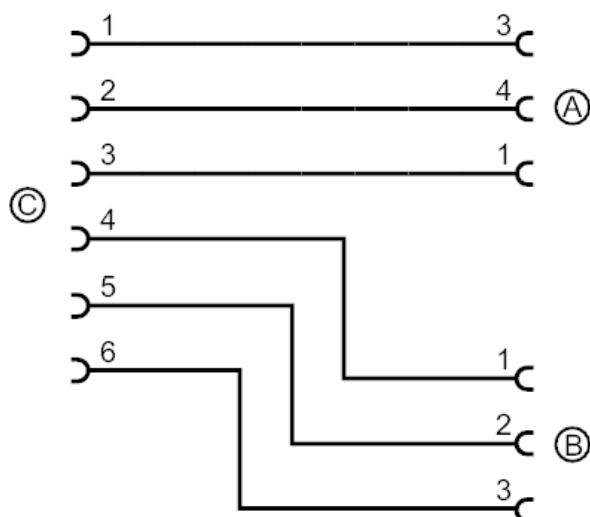


Konektor: 1 x Konektor DEUTSCH, lurus



Koneksi listrik - soket A

Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 5.4 mm; 3 x 0.50 mm² (28 x Ø 0.15 mm)

Konektor: 1 x M12, lurus; pengkodean: A; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.6...1.5 Nm

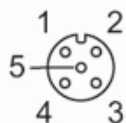



Kabel koneksi Y

YDOGS060--S0005H03DOGH030MSS

Koneksi listrik - soket B

Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 5.4 mm; 3 x 0.50 mm² (28 x Ø 0.15 mm)

Konektor: 1 x M12, lurus; pengkodean: A; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.6...1.5 Nm

