


Kabel koneksi Y

YDOGS060--S0002H03DOGH030MSS

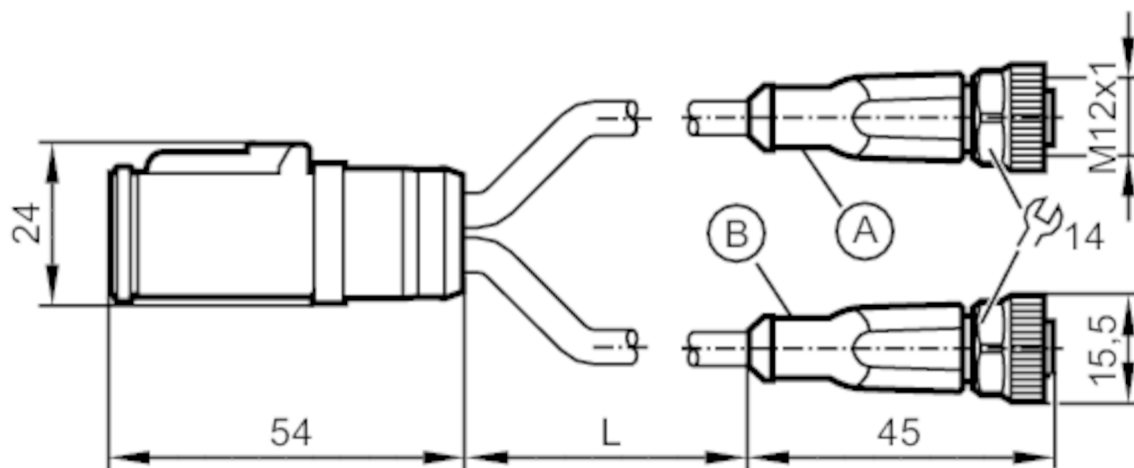

Aplikasi

Fitur khusus	Bebas dari silikon; Bebas halogen; Kesesuaian rantai tarik
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian [V]	8...32 DC
Kelas perlindungan	III
Total beban arus maks. [A]	4

Kondisi pengoperasian

Suhu sekitar [°C]	-40...80
Suhu sekitar (bergerak) [°C]	-20...80
Perlindungan	IP 67; (pasangan konektor terpasang)

Data teknis

Berat [g]	226.3
Material	PA; soket: TPU oranye; Segel: FKM
Material mur	kuningan, berlapis nikel
Jumlah port kotak splitter	2
Kesesuaian rantai tarik	ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel
	min. 10 x diameter kabel
	kecepatan pergerakan
	maks. 3,3 m/dtk untuk panjang pergerakan horizontal 5 m dan akselerasi maks. 5 m/dtk ²
	siklus pembengkokan
	> 5 Mio.
	ketegangan torsional
	± 180 °/m

Keterangan


Jumlah paket	1 buah
--------------	--------

Kabel koneksi Y

YDOGS060--S0002H03DOGH030MSS

Koneksi listrik - Konektor DEUTSCH C

Koneksi

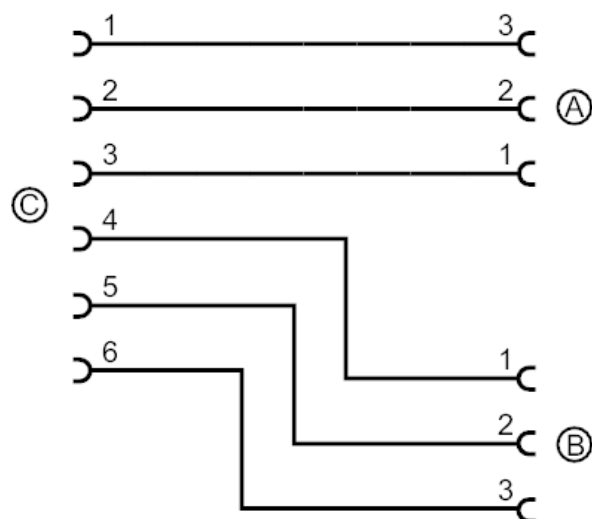


Konektor: 1 x Konektor DEUTSCH, lurus



Koneksi listrik - soket A

Kabel: 2 m, PUR, Bebas halogen, hitam, Ø 5.4 mm; 3 x 0.50 mm² (28 x Ø 0.15 mm)

Konektor: 2 x M12, lurus; pengkodean: A; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.6...1.5 Nm

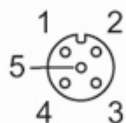



Kabel koneksi Y

YDOGS060--S0002H03DOGH030MSS

Koneksi listrik - soket B

Kabel: 2 m, PUR, Bebas halogen, hitam, Ø 5.4 mm; 3 x 0.50 mm² (28 x Ø 0.15 mm)

Konektor: 2 x M12, lurus; pengkodean: A; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.6...1.5 Nm

