


Soket berkabel

ecomatPanel/Connection Set

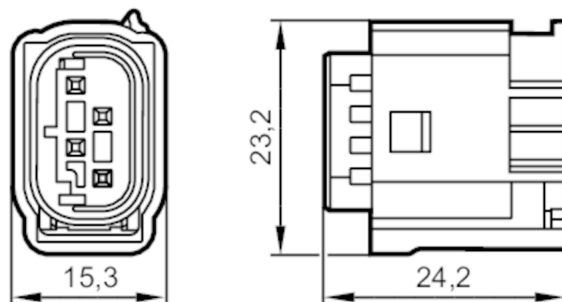

Data kelistrikan

Tegangan pengoperasian	[V]	8...32 DC
Kelas perlindungan		III
Total beban arus maks.	[A]	4

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...80
Perlindungan		IP 20; (tanpa resistor)

Data teknis

Berat	[g]	10
Dimensi	[mm]	15.3 x 23.2 x 24.2
Material		casing: PBT-GF20
Material bodi detakan		PBT

Aksesori

Item dikirim		resistor 120 Ohm
		Kontak Crimp
		tabung pelindung

Keterangan

Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

5 x 0.5...0.75 mm²

Konektor: AMP MQS, lurus; Bodi cetakan: PBT; Kontak: dilapisi timah





Soket berkabel

ecomatPanel/Connection Set

Koneksi

