


E12775



Colokan berkabel

SSTGB030ZDSFKPG

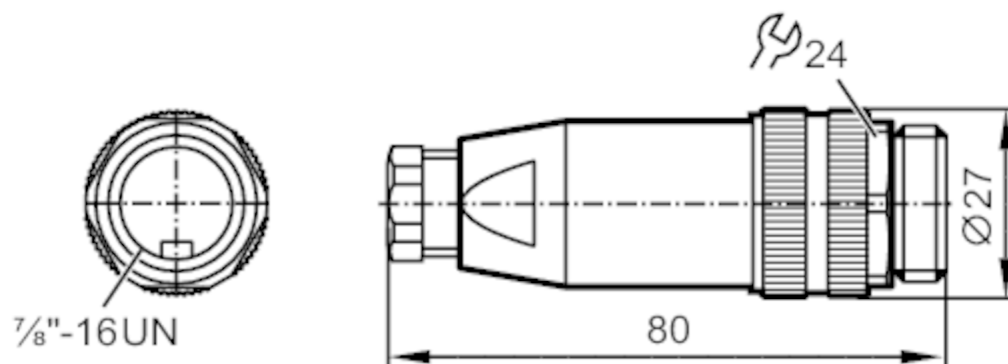

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian

[V]

< 300 AC/DC

Kelas perlindungan

II

Total beban arus maks.

[A]

12

Kondisi pengoperasian

Suhu sekitar

[°C]

-25...85

Perlindungan

IP 67

Data teknis

Berat

[g]

51.9

Material bodi detakan

PBT

Material mur

seng tuang, berlapis nikel

Keterangan

Keterangan

pengarah pin 1

Jumlah paket

1 buah

E12775



Colokan berkabel

SSTGB030ZDSFKPG

Koneksi listrik

terminal sekrup: ...1.5 mm²; Selubung kabel: Ø 6...8 mm; AWG 16

Koneksi listrik - colokan

Konektor: 1 x 7/8", lurus; Bodi cetakan: PBT; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas



Koneksi

