


# E12776



## Colokan berkabel

SSTGB050ZDSFKPG

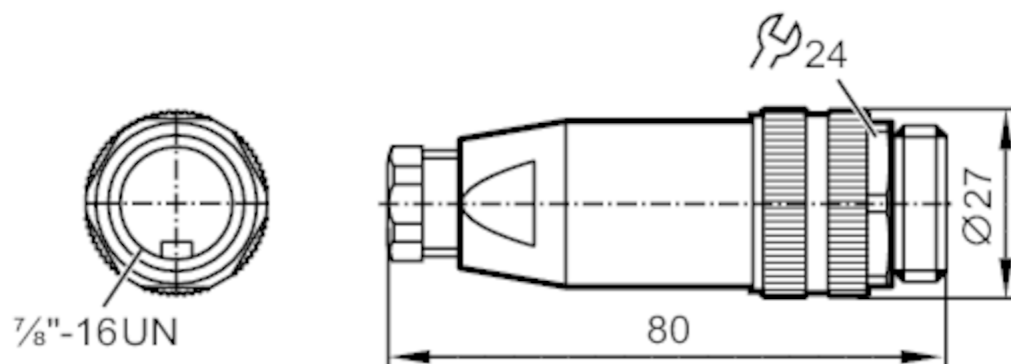

### Aplikasi

Fitur khusus

Kontak berlapis emas

### Data kelistrikan

Tegangan pengoperasian

[V]

< 300 AC/DC

Kelas perlindungan

II

Total beban arus maks.

[A]

9

### Kondisi pengoperasian

Suhu sekitar

[°C]

-25...85

Perlindungan

IP 67

### Data teknis

Berat

[g]

54.7

Material bodi detakan

PBT

Material mur

seng tuang, berlapis nikel

### Keterangan

Keterangan

Pengarah Pin 4

Jumlah paket

1 buah

# E12776



## Colokan berkabel

SSTGB050ZDSFKPG

### Koneksi listrik

terminal sekrup: ...1.5 mm<sup>2</sup>; Selubung kabel: Ø 6...8 mm; AWG 16

### Koneksi listrik - colokan

Konektor: 1 x 7/8", lurus; Bodi cetakan: PBT; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas



### Koneksi

