


E12090



Kabel koneksi Ethernet

VSTGN040ZDS0002L04STGP040--S

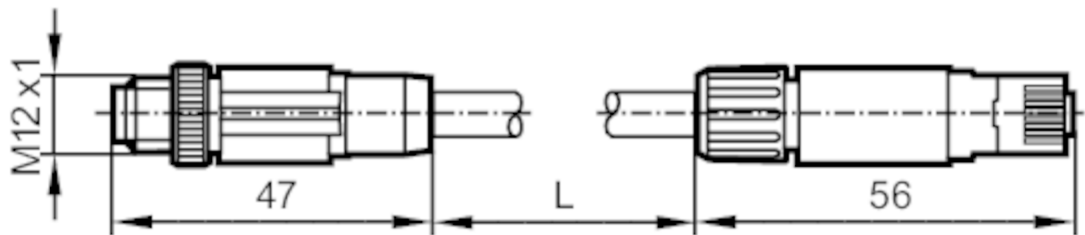

Aplikasi		
Fitur khusus		Kabel berpelindung
Desain		Kabel Ethernet, Dengan kode D
Aplikasi		kabel patch silang; kabel patch
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...70
Perlindungan		IP 67; IP 20; (Colokan M12/colokan RJ45)
Data teknis		
Berat	[g]	166.7
Material		TPU / PA
Material bodi detakan		PA / TPU
Material mur		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah

Kabel koneksi Ethernet

VSTGN040ZDS0002L04STGP040--S

Koneksi listrik - colokan M12


Konektor: 1 x M12, lurus; pengkodean: D; Bodi cetakan: PA; Penguncian: seng tuang, berlapis nikel; Torsi pengencangan: 0.7...0.9 Nm



Koneksi listrik

Kabel: 2 m, PVC, hijau, Ø 6.5 mm, berpelindung; 2 x 2 x 0.38 mm²

Koneksi

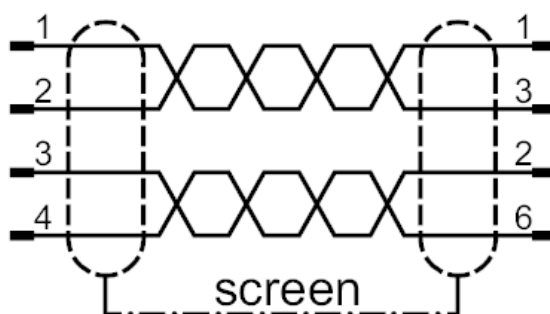

Koneksi listrik - colokan RJ45

Konektor: 1 x RJ45, lurus; Bodi cetakan: TPU

