




Kabel koneksi dengan soket

ADOGH080MSS0010B08

Untuk soket 8 terminal, warna core tidak distandarisasi.
Perhatikan perkabelan sensor dan soket (lihat lembar data).

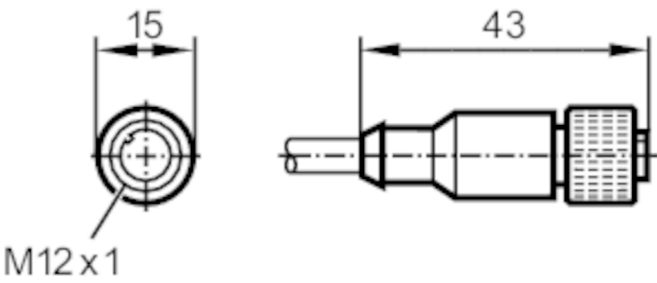

Aplikasi		
Fitur khusus		Kesesuaian rantai tarik
Data kelistrikan		
Tegangan pengoperasian	[V]	< 30 AC / < 36 DC
Total beban arus maks.	[A]	2
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...80
Perlindungan		IP 67
Data teknis		
Berat	[g]	537.5
Dimensi	[mm]	15 x 15 x 43
Material		casing: TPU hitam
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 15 x diameter kabel
	kecepatan pergerakan	maks. 3 m/s
	siklus pembengkokan	> 1 Mio.
	ketegangan torsional	± 30 °/m

E12167



Kabel koneksi dengan soket

ADOGH080MSS0010B08

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 10 m, PUR, hitam; 8 x 0.25 mm² (32 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 1...1.5 Nm



Koneksi

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	RD

warna sesuai DIN 47100	Warna core :
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
WH =	putih
YE =	kuning