


E12238



Kabel koneksi dengan soket

ADOAH080MSS0025B08

Untuk soket 8 terminal, warna core tidak distandarisasi.
Perhatikan perkabelan sensor dan soket (lihat lembar data).

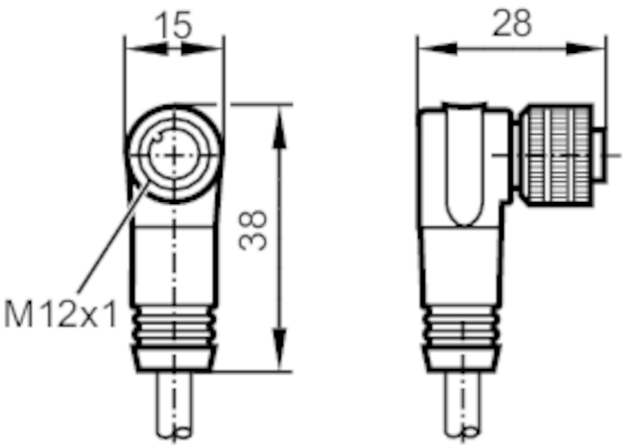

Data kelistrikan		
Tegangan pengoperasian	[V]	< 30 AC / < 36 DC
Total beban arus maks.	[A]	2
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...80
Perlindungan		IP 68
Data teknis		
Berat	[g]	1206
Dimensi	[mm]	28 x 15 x 38
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah

E12238



Kabel koneksi dengan soket

ADOAH080MSS0025B08

Koneksi listrik

Kabel: 25 m, PUR, hitam; 8 x 0.25 mm² (32 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 1...1.5 Nm



Koneksi

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	RD

warna sesuai DIN
47100

Warna core :

BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
WH =	putih
YE =	kuning