


Kabel koneksi

VDOGF030MSS0005H03DOGR030PLS

Produk tidak tersedia - entri arsip

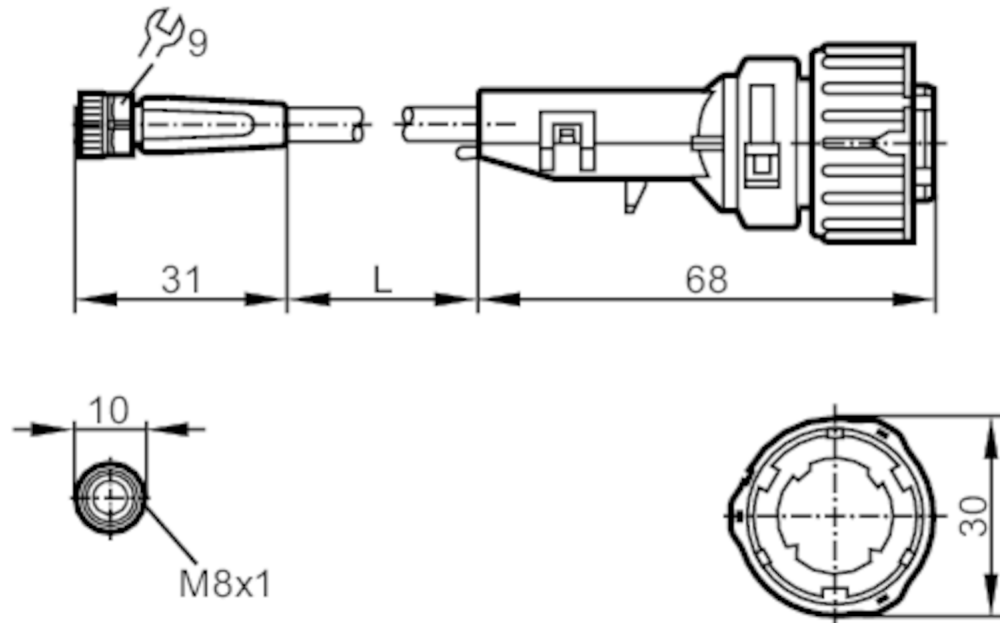

Aplikasi

Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas; Kesesuaian rantai tarik
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	9.6...30 DC
Kelas perlindungan		III
Total beban arus maks.	[A]	3

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67; IP 69K

Data teknis

Berat	[g]	124.2
Dimensi	[mm]	10 x 10 x 31
Material		casing: TPU oranye; Segel: FKM; casing: Hytrel G-4774 hitam
Material mur		kuningan, berlapis nikel
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	kecepatan pergerakan	maks. 3,3 m/dtk untuk panjang pergerakan horizontal 5 m dan akselerasi maks. 5 m/dtk ²
	siklus pembengkokan	> 5 Mio.
	ketegangan torsional	± 180 °/m

Keterangan

Jumlah paket	1 buah
--------------	--------

 


Kabel koneksi

VDOGF030MSS0005H03DOGR030PLS

Koneksi listrik - soket


Konektor: 1 x M8, lurus; pengkodean: A; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.3...0.5 Nm



Koneksi listrik

Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 3.7 mm; 3 x 0.25 mm² (32 x Ø 0.1 mm)

Koneksi

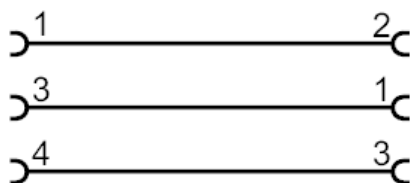

Koneksi listrik - soket

Konektor: 1 x bayonet, lurus; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.3...0.5 Nm

