


Colokan berkabel

SSTGH040MSSFKSG

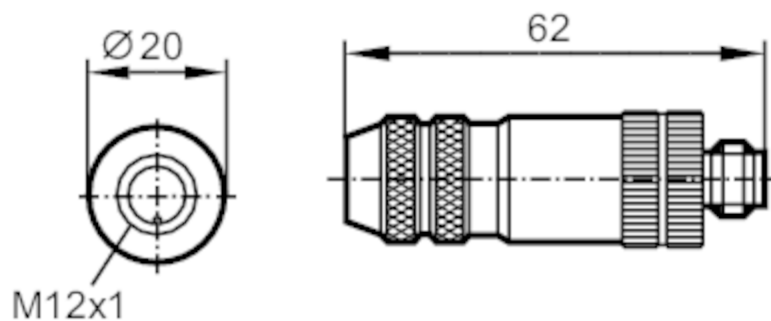

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC/DC
Total beban arus maks.	[A]	4; (...40 °C)

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67

Data teknis

Berat	[g]	44.5
Dimensi	[mm]	20 x 20 x 62
Material		seng tuang berlapis nikel
Material bodi detakan		seng tuang, berlapis nikel
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------



Colokan berkabel

SSTGH040MSSFKSG

Koneksi listrik

terminal sekrup: ...0.75 mm²; Selubung kabel: Ø 6...8 mm

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: seng tuang, berlapis nikel; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Kabel koneksi berpelindung: dapat dilindungi



Koneksi

