


Colokan berkabel

SSTGH040MSSFKPG

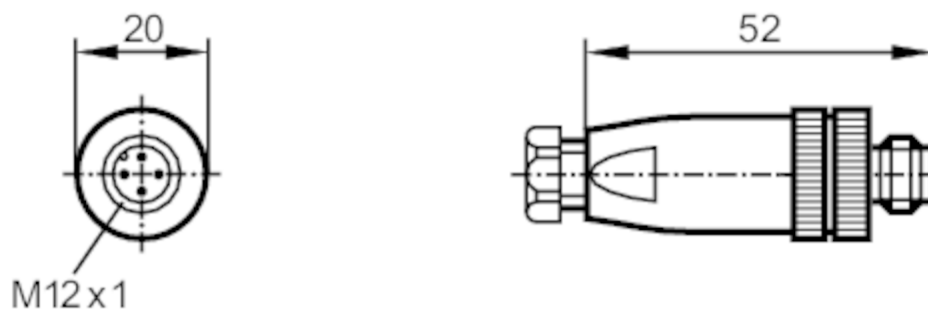

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	< 45 AC / < 70 DC
Total beban arus maks.	[A]	4; (...40 °C)

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68

Data teknis

Berat	[g]	24.9
Dimensi	[mm]	20 x 20 x 52
Material		PA
Material bodi detakan		PA
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E12266



Colokan berkabel

SSTGH040MSSFKPG

Koneksi listrik

terminal sekrup: ...0.75 mm²; Selubung kabel: Ø 2.5...3.5 mm

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PA; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas



Koneksi

