


E12283



Kabel koneksi Ethernet

VSTGN040ZDS0005L04STGP040--S

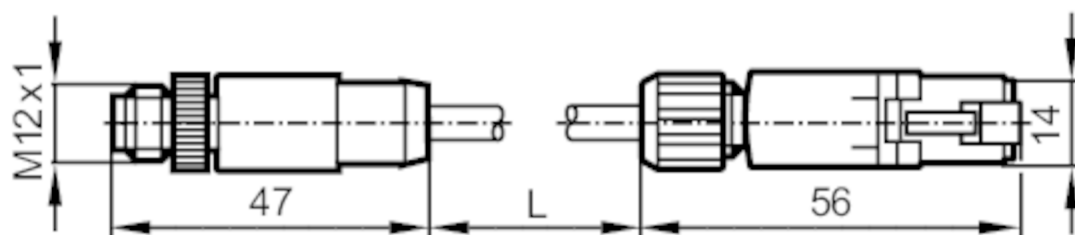

Aplikasi

Fitur khusus	Kabel berpelindung
Desain	Kabel Ethernet, Dengan kode D
Aplikasi	kabel patch silang; kabel patch

Kondisi pengoperasian

Suhu sekitar [°C]	-25...70
Perlindungan	IP 67; IP 42; (Colokan M12/colokan RJ45)

Data teknis

Berat [g]	371.3
Material	PUR / PC
Material bodi detakan	PUR / PC
Material mur	seng tuang, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------

Kabel koneksi Ethernet

VSTGN040ZDS0005L04STGP040--S

Koneksi listrik - colokan M12


Konektor: 1 x M12, lurus; pengkodean: D; Bodi cetakan: PUR; Penguncian: seng tuang, berlapis nikel; Torsi pengencangan: 0.7...0.9 Nm



Koneksi listrik

Kabel: 5 m, PVC, hijau, Ø 6.2 mm, berpelindung; 4 x 0.38 mm²

Koneksi

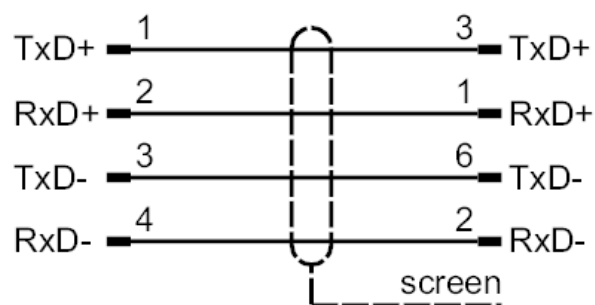

Koneksi listrik - colokan RJ45

Konektor: 1 x RJ45, lurus; Bodi cetakan: PC; Kabel koneksi berpelindung: berpelindung

