


E12289



Colokan berkabel

SSTGN040ZDSFKSG

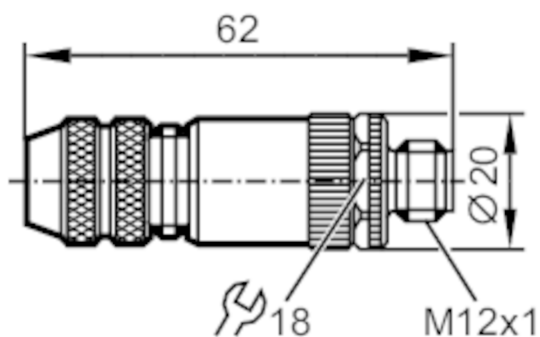

Aplikasi		
Fitur khusus		Bebas dari silikon; Kontak berlapis emas
Desain		Kabel Ethernet, Dengan kode D
Bebas dari silikon		ya
Data kelistrikan		
Tegangan pengoperasian	[V]	< 45 AC / < 70 DC
Total beban arus maks.	[A]	4; (...40 °C)
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67
Data teknis		
Berat	[g]	44.6
Dimensi	[mm]	20.2 x 20.2 x 63
Material		seng tuang berlapis nikel
Material bodi detakan		seng tuang, berlapis nikel
Material mur		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah



Colokan berkabel

SSTGN040ZDSFKSG

Koneksi listrik

terminal sekrup: ...0.75 mm²; Selubung kabel: Ø 6...8 mm; AWG 18

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: D; Bodi cetakan: seng tuang, berlapis nikel; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Kabel koneksi berpelindung: dapat dilindungi



Koneksi

