


Splitter Y

Y-Splitter M12/2xM12 DO/ST

Produk tidak tersedia - entri arsip

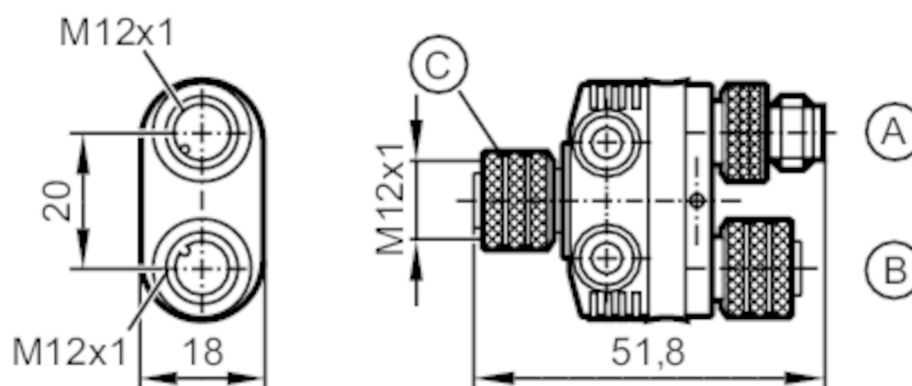

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC/DC
Beban arus maks. per modul/slot	[A]	4
Total beban arus maks.	[A]	4

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Berat	[g]	29.6
Material		PUR
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel

Keterangan


Jumlah paket	1 buah
--------------	--------

Splitter Y

Y-Splitter M12/2xM12 DO/ST

Koneksi listrik

Koneksi

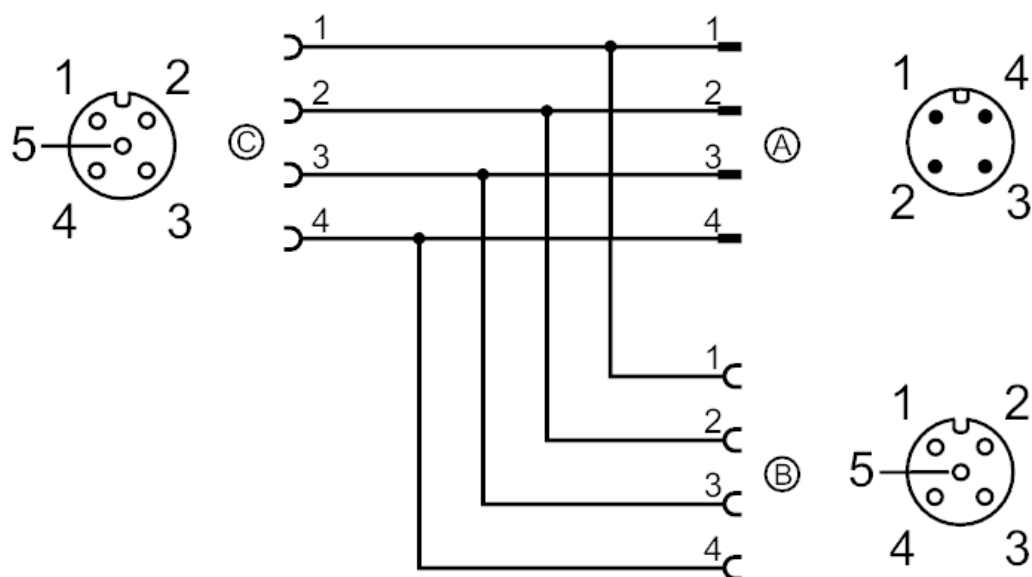

Koneksi listrik - colokan

Konektor: 1 x M12; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

Koneksi listrik - soket

Konektor: 1 x M12; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

Konektor: 1 x M12; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas