


E12332



Kabel koneksi

VDOGH040MSS0015C04STGH040MSS

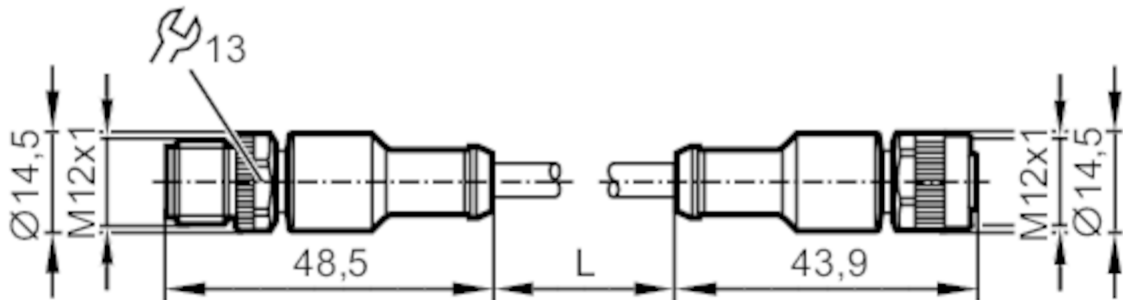

Aplikasi		
Fitur khusus		Bebas dari silikon; Kontak berlapis emas; Kabel berpelindung
Bebas dari silikon		ya
Data kelistrikan		
Tegangan pengoperasian	[V]	< 50 AC / < 60 DC
Kelas perlindungan		III
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68
Data teknis		
Berat	[g]	612.5
Dimensi	[mm]	14.5 x 14.5 x 48.5
Material		PUR
Material bodi detakan		PUR
Material mur		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah

Kabel koneksi

VDOGH040MSS0015C04STGH040MSS

Koneksi listrik - colokan


Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.7...0.9 Nm



Koneksi listrik

Kabel: 15 m, PUR, hitam, Ø 5 mm, berpelindung; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi

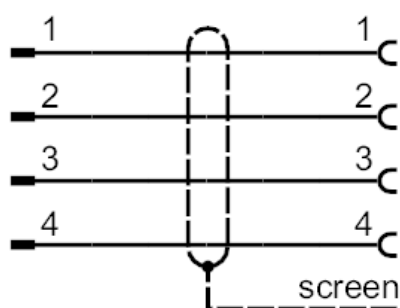

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.7...0.9 Nm

