


Kabel koneksi dengan colokan

ASTGH040MSS0010C04

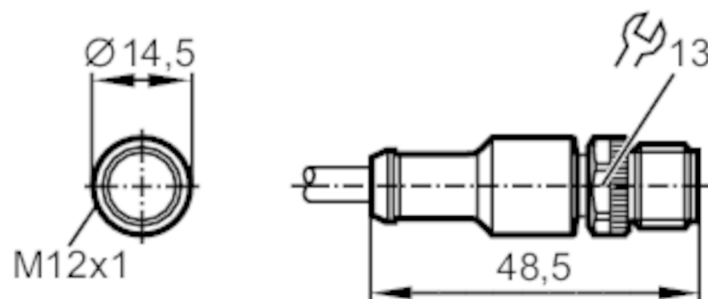

Aplikasi		
Fitur khusus		Bebas dari silikon; Bebas halogen; Kontak berlapis emas; Kabel berpelindung
Bebas dari silikon		ya
Data kelistrikan		
Tegangan pengoperasian	[V]	< 50 AC / < 60 DC
Kelas perlindungan		III
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 68
Data teknis		
Berat	[g]	386.2
Dimensi	[mm]	14.5 x 14.5 x 48.4
Material		PUR
Material bodi detakan		PUR
Material mur		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah

Kabel koneksi dengan colokan

ASTGH040MSS0010C04

Koneksi listrik


Kabel: 10 m, PUR, Bebas halogen, hitam, Ø 5 mm, berpelindung; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.7...0.9 Nm; Kabel koneksi berpelindung: layar tidak terhubung



Koneksi

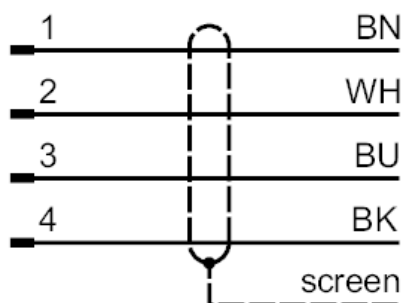

Warna core :
 BK = hitam
 BN = coklat
 BU = biru
 WH = putih