


Kabel koneksi

VDOGH040MSS0,75H04STGX040--S

Produk tidak tersedia - entri arsip

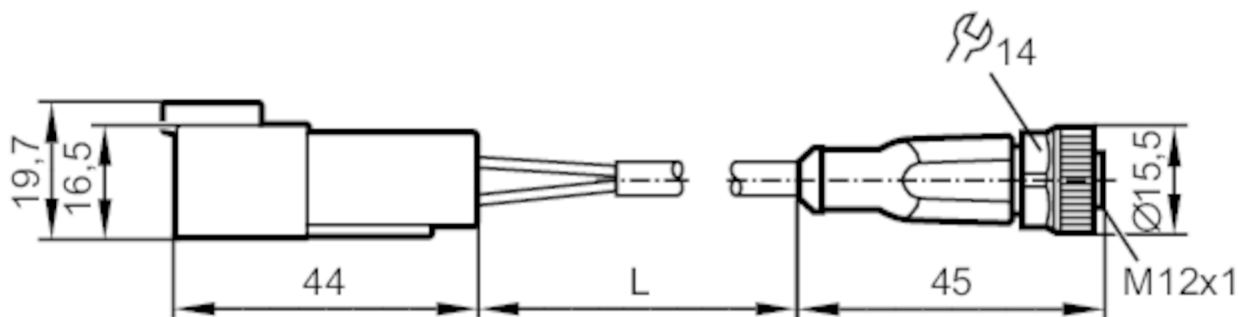

Aplikasi

Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas; Kesesuaian rantai tarik
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	10...36 DC
Kelas perlindungan		II
Total beban arus maks.	[A]	4

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Berat	[g]	54.6
Material		casing soket: TPU oranye; Segel: FKM
Material mur		kuningan, berlapis nikel
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	kecepatan pergerakan	maks. 3,3 m/dtk untuk panjang pergerakan horizontal 5 m dan akselerasi maks. 5 m/dtk ²
	siklus pembengkokan	> 5 Mio.
	ketegangan torsional	± 180 °/m

Keterangan

Jumlah paket	1 buah
--------------	--------

E12345



Kabel koneksi

VDOGH040MSS0,75H04STGX040--S

Koneksi listrik - colokan


Konektor: 1 x Konektor DEUTSCH, lurus; Kontak: berlapis nikel



Koneksi listrik

Kabel: 0.75 m, PUR, Bebas halogen, hitam, Ø 5.1 mm; 4 x 0.50 mm² (64 x Ø 0.1 mm)

Koneksi

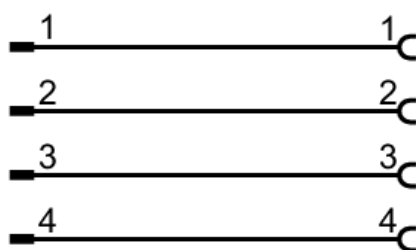

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.6...1.5 Nm

