


E12353



Colokan berkabel

SSTA040MSSFKSG

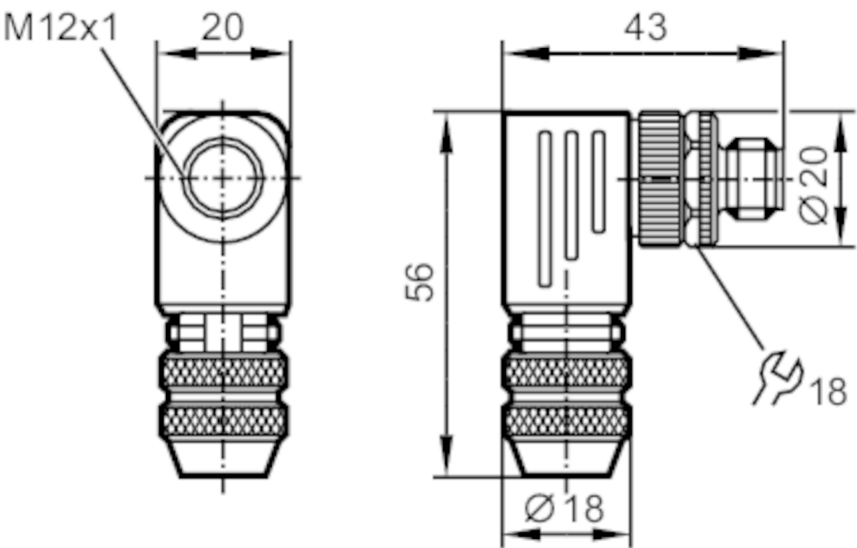

Aplikasi		
Fitur khusus		Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon		ya
Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC/DC
Total beban arus maks.	[A]	4; (...40 °C)
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67
Data teknis		
Berat	[g]	66.7
Dimensi	[mm]	42 x 20 x 54
Material		seng tuang berlapis nikel
Material bodi detakan		seng tuang, berlapis nikel
Material mur		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah

E12353



Colokan berkabel

SSTAH040MSSFKSG

Koneksi listrik

terminal sekrup: ...0.75 mm²; Selubung kabel: Ø 6...8 mm

Koneksi listrik - colokan

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: seng tuang, berlapis nikel; Penguncian: seng tuang, berlapis nikel;
Kontak: dilapisi emas; Kabel koneksi berpelindung: dapat dilindungi



Koneksi

