


E12354



Soket berkabel

SDOGH040MSSFKSG

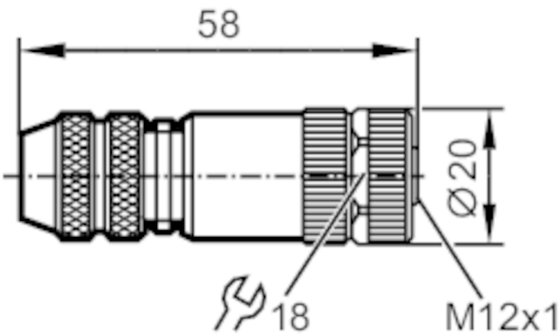

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Desain	Kabel Ethernet, Dengan kode D
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	< 45 AC / < 70 DC
Total beban arus maks.	[A]	4; (...40 °C)

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67

Data teknis

Berat	[g]	46.7
Dimensi	[mm]	20 x 20 x 58
Material		seng tuang berlapis nikel
Material bodi detakan		seng tuang, berlapis nikel
Material mur		seng tuang, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E12354



Soket berkabel

SDOGH040MSSFKSG

Koneksi listrik

terminal sekrup: ...0.75 mm²; Selubung kabel: Ø 6...8 mm

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: D; Bodi cetakan: seng tuang, berlapis nikel; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Kabel koneksi berpelindung: dapat dilindungi



Koneksi

