


E12356



Soket berkabel

SDOGH040MSSFKSG

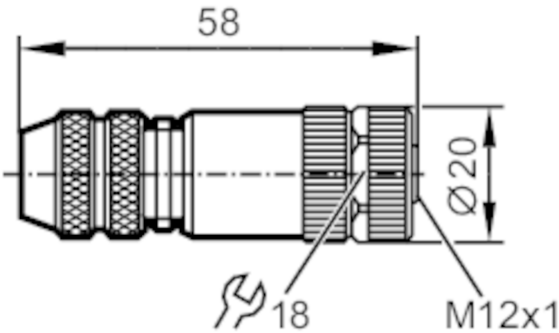

Aplikasi		
Fitur khusus		Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon		ya
Data kelistrikan		
Tegangan pengoperasian	[V]	< 45 AC / < 70 DC
Total beban arus maks.	[A]	4; (...40 °C)
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67
Data teknis		
Berat	[g]	47.6
Dimensi	[mm]	20 x 20 x 58
Material		seng tuang berlapis nikel
Material bodi detakan		seng tuang, berlapis nikel
Material mur		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah

E12356



Soket berkabel

SDOGH040MSSFKSG

Koneksi listrik

terminal sekrup: ...0.75 mm²; Selubung kabel: Ø 6...8 mm

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: B; Bodi cetakan: seng tuang, berlapis nikel; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Kabel koneksi berpelindung: dapat dilindungi



Koneksi

