




Colokan adaptor

ESTGH040PLS00,5E04 (PG11)

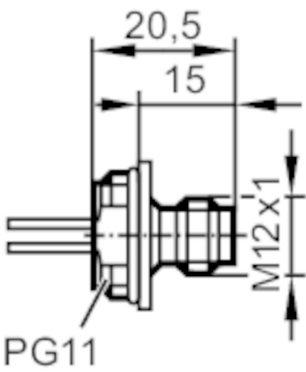

1 O-ring



Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC/DC
Total beban arus maks.	[A]	4; (...40 °C)
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67
Data teknis		
Berat	[g]	9.66
Ulir pemasangan		PG 11
Material		PA 6.6
Material bodi detakan		PA 6.6
Keterangan		
Jumlah paket		1 buah

**Colokan adaptor**

ESTGH040PLS00,5E04 (PG11)

Koneksi listrikKabel: 0.5 m, PVC; 4 x 0.25 mm²**Koneksi listrik - colokan**

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PA 6.6

**Koneksi**

1	BN
2	WH
3	BU
4	BK

BK = Warna core :
BN = hitam
BU = coklat
WH = biru
 putih