


E18001



Kabel koneksi dengan soket

ADOGH040MKS0010X04

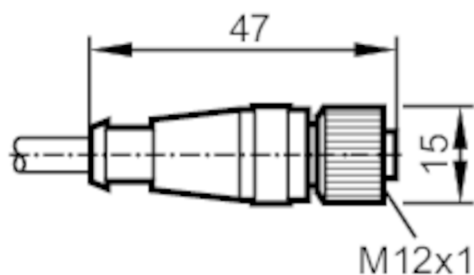

Aplikasi

Fitur khusus	Kontak berlapis emas
--------------	----------------------

Data kelistrikan

Tegangan pengoperasian	[V]	< 300 AC/DC
------------------------	-----	-------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-45...105
Perlindungan		IP 68

Data teknis

Berat	[g]	361.966
Dimensi	[mm]	15 x 15 x 47
Material		TPE
Material bodi detakan		TPE
Material mur		seng, dilapisi epoksi

Keterangan

Jumlah paket	1 buah
--------------	--------

E18001



Kabel koneksi dengan soket

ADOGH040MKS0010X04

Koneksi listrik


Kabel: 10 m, TPE-S, hitam; 4 x 0.75 mm² / AWG 18

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPE; Penguncian: seng, dilapisi epoksi; Kontak: dilapisi emas



Koneksi

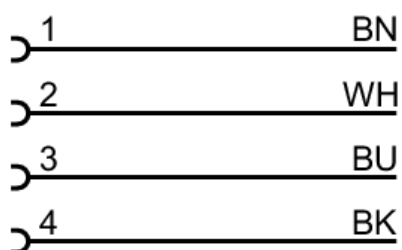

BK =	Warna core :
BN =	hitam
BU =	coklat
WH =	biru
	putih