


E18002



Kabel koneksi dengan soket

ADOAH040MKS0005X04

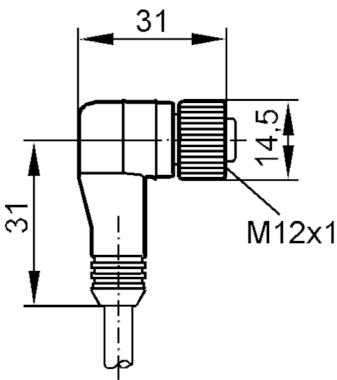

Aplikasi		
Fitur khusus		Kontak berlapis emas
Data kelistrikan		
Tegangan pengoperasian	[V]	< 300 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-45...105
Perlindungan		IP 68
Data teknis		
Berat	[g]	385.553
Dimensi	[mm]	31 x 14.5 x 31
Material		TPE
Material bodi detakan		TPE
Material mur		seng, dilapisi epoksi
Keterangan		
Jumlah paket		1 buah

E18002



Kabel koneksi dengan soket

ADOAH040MKS0005X04

Koneksi listrik

Kabel: 5 m, TPE-S, hitam; 4 x 0.75 mm² / AWG 18

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPE; Penguncian: seng, dilapisi epoksi; Kontak: dilapisi emas



Koneksi



BK = Warna core :
BN = hitam
BU = coklat
WH = biru
 putih