


E18003



Kabel koneksi dengan soket

ADOAH040MKS0010X04

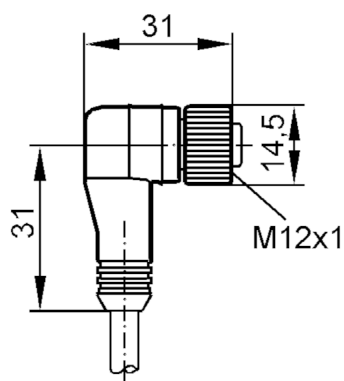

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian

[V]

< 300 AC/DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-45...105

Perlindungan

IP 68

Data teknis

Berat

[g]

361.966

Dimensi

[mm]

31 x 14.5 x 31

Material

TPE

Material bodi detakan

TPE

Material mur

seng, dilapisi epoksi

Keterangan

Jumlah paket

1 buah

E18003



Kabel koneksi dengan soket

ADOAH040MKS0010X04

Koneksi listrik


Kabel: 10 m, TPE-S, hitam; 4 x 0.75 mm² / AWG 18

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPE; Penguncian: seng, dilapisi epoksi; Kontak: dilapisi emas



Koneksi

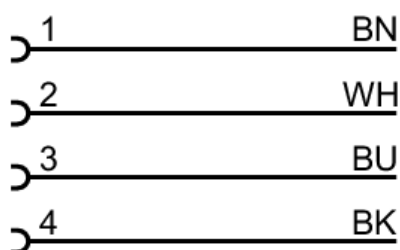

BK =	Warna core :
BN =	hitam
BU =	coklat
WH =	biru
	putih