



Kabel koneksi dengan soket

ADOGH040MSS0005G04

No scale drawing available

Aplikasi

Fitur khusus

Kabel berpelindung

Data kelistrikan

Tegangan pengoperasian

[V]

< 250 DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-40...90

Perlindungan

IP 68

Data teknis

Berat

[g]

254.012

Material

PUR

Material bodi detakan

PUR

Material mur

kuningan, berlapis nikel

Keterangan

Jumlah paket

1 buah

Koneksi listrik

Kabel: 5 m, PVC, kuning, Ø 5.6 mm, berpelindung; 4 x 0.34 mm² / AWG 22

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm




E18025



Kabel koneksi dengan soket

ADOGH040MSS0005G04

Koneksi

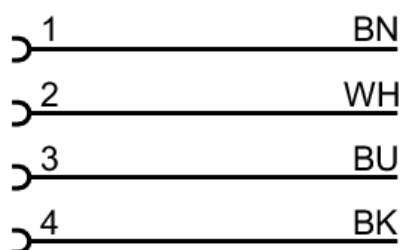

BN =	Warna core :	coklat
BK =		hitam
BU =		biru
WH =		putih