


E18031



Soket berkabel

SDOGH040MSSFKPG

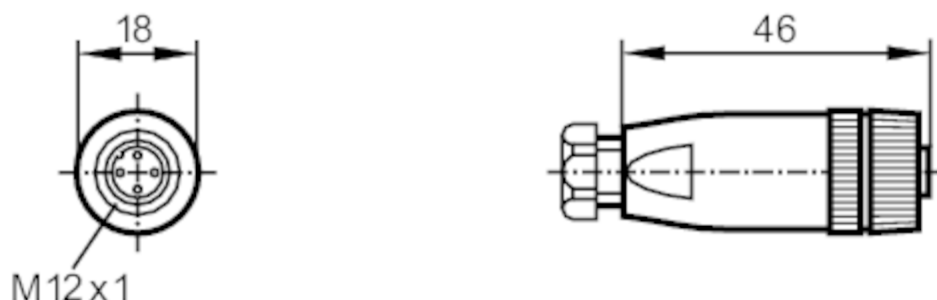

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian

[V]

< 250 AC/DC

Total beban arus maks.

[A]

4; (...40 °C)

Kondisi pengoperasian

Suhu sekitar

[°C]

-25...90

Perlindungan

IP 67

Data teknis

Berat

[g]

27.216

Dimensi

[mm]

18 x 18 x 46

Material

PA

Material bodi detakan

PA

Material mur

ZnAl / Ni

Keterangan

Jumlah paket

1 buah

E18031



Soket berkabel

SDOGH040MSSFKPG

Koneksi listrik

terminal: ...0.75 mm²; Selubung kabel: Ø 8...10 mm

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PA; Penguncian: ZnAl / Ni; Kontak: dilapisi emas



Koneksi

