





Kabel koneksi

VSTGH050VAS00.3E03VDAA030--S

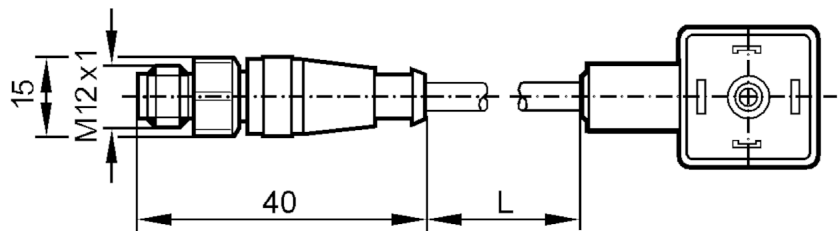

Aplikasi		
Fitur khusus		Kontak berlapis emas
Data kelistrikan		
Frekuensi AC	[Hz]	47...63
Tegangan pengoperasian	[V]	< 24 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...105
Perlindungan		IP 68
Data teknis		
Berat	[g]	54.431
Material		TPE
Material bodi detakan		TPE
Material mur		baja tahan karat (1.4571 / 316Ti)
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - colokan		
Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPE; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas		

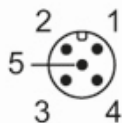




Kabel koneksi

VSTGH050VAS00.3E03VDAA030--S

Koneksi listrik

Kabel: 0.3 m, PVC, abu-abu; 3 x 0.34 mm² / AWG 22

Koneksi

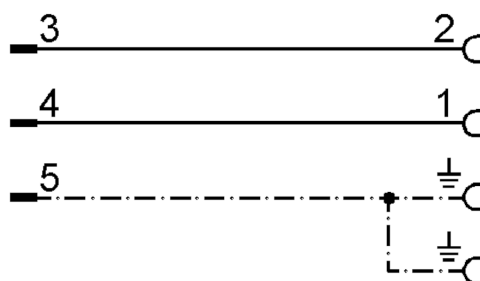

Koneksi listrik - soket

Konektor: 1 x katup tipe A DIN, bersiku; Bodi cetakan: TPE; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas

