


Colokan adaptor

RSTGH040VAS0001-04

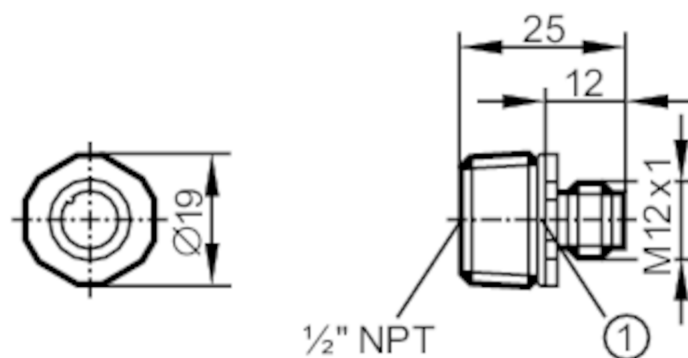

1 O-ring

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 DC
------------------------	-----	----------

Kondisi pengoperasian

Suhu sekitar	[°C]	-20...90
--------------	------	----------

Data teknis

Berat	[g]	54.431
Ulir pemasangan		1/2" NPT
Material		baja tahan karat (1.4401/316)
Material bodi detakan		baja tahan karat (1.4401/316)

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 1 m, PVC; 4 x 0.34 mm² / AWG 22

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: baja tahan karat (1.4401/316)





Colokan adaptor

RSTGH040VAS0001-04

Koneksi

1	BN
2	WH
3	BU
4	BK

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
WH =	putih