


E18065




Kabel koneksi

VDOAH040VAS0003E03STGH040VAS

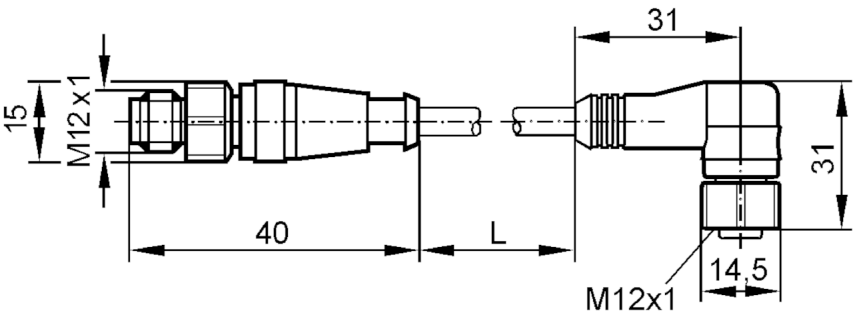

Aplikasi	
Fitur khusus	Kontak berlapis emas
Data kelistrikan	
Tegangan pengoperasian [V]	< 300 AC/DC
Kondisi pengoperasian	
Suhu sekitar [°C]	-20...105
Perlindungan	IP 68
Data teknis	
Berat [g]	136.078
Material	PVC
Material bodi detakan	PVC
Material mur	baja tahan karat (1.4571 / 316Ti)
Keterangan	
Jumlah paket	1 buah
Koneksi listrik - colokan	

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas

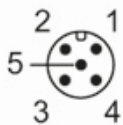



Kabel koneksi

VDOAH040VAS0003E03STGH040VAS

Koneksi listrik

Kabel: 3 m, PVC, abu-abu; 3 x 0.34 mm² / AWG 22

Koneksi



Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas

