


Colokan adaptor

RSTGB030VAS00.3-03

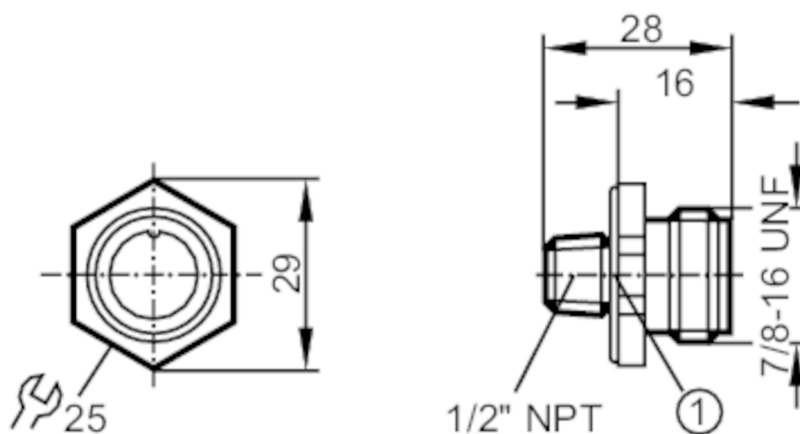

1 O-ring

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian

[V]

< 600 AC/DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-20...100

Perlindungan

IP 68

Data teknis

Berat

[g]

25.855

Ulir pemasangan

1/2" NPT

Material

baja tahan karat

Material bodi detakan

baja tahan karat

Keterangan

Jumlah paket

1 buah



Colokan adaptor

RSTGB030VAS00.3-03

Koneksi listrik


, PVC; 3 x 1.5 mm² / AWG 16

Koneksi listrik - colokan

Konektor: 1 x 7/8", lurus; pengkodean: A; Bodi cetakan: baja tahan karat; Kontak: dilapisi emas



Koneksi

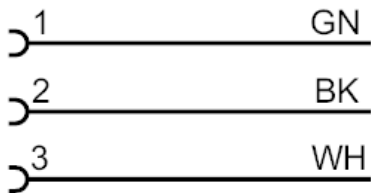

BK = Warna core :
GN = hitam
WH = hijau
 putih