


Colokan adaptor

RSTGB030ALS00.3-03

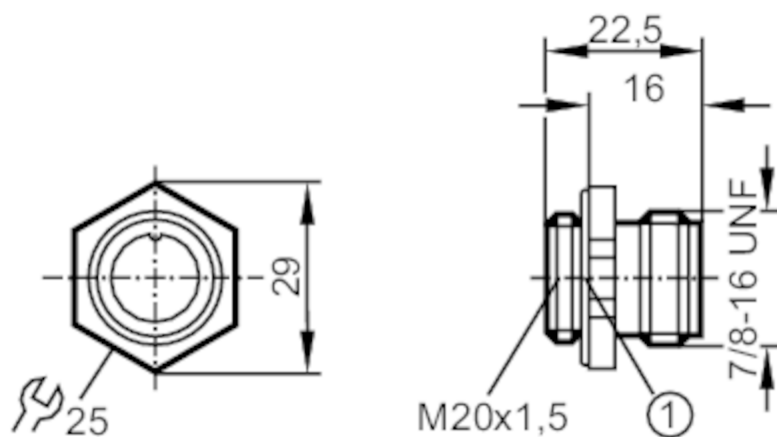

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian

[V]

< 600 AC/DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-20...100

Perlindungan

IP 68

Data teknis

Berat

[g]

36.287

Ulir pemasangan

M20 x 1,5

Material

kuningan berlapis nikel

Material bodi detakan

kuningan, berlapis nikel

Keterangan

Jumlah paket

 
1 buah

Koneksi listrik

Kabel: 0.3 m, PVC; 3 x 1.5 mm² / AWG 16

Koneksi listrik - colokan

Konektor: 1 x 7/8", lurus; pengkodean: A; Bodi cetakan: kuningan, berlapis nikel; Kontak: dilapisi emas



E18070



Colokan adaptor

RSTGB030ALS00.3-03

Koneksi

1	GN
2	BK
3	WH

	Warna core :
BK =	hitam
GN =	hijau
WH =	putih