


Colokan adaptor

RSTGB050PLS00.3-05

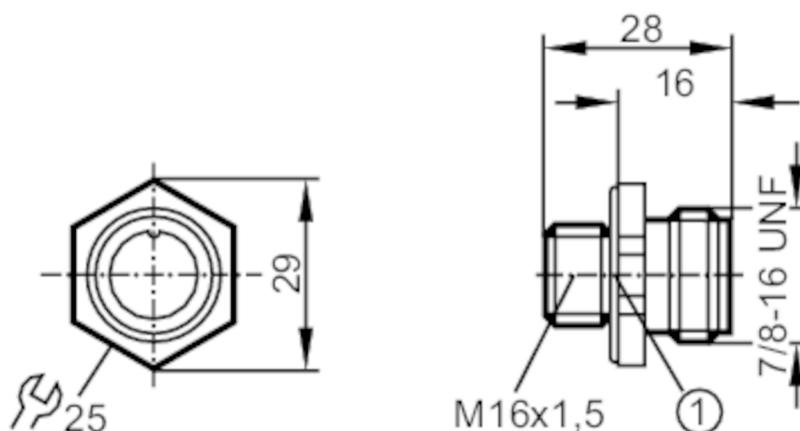

1 O-ring

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian

[V]

< 600 AC/DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-20...100

Perlindungan

IP 68

Data teknis

Berat

[g]

27.216

Ulir pemasangan

M16 x 1,5

Material

plastik

Material bodi detakan

plastik

Keterangan

Jumlah paket

1 buah



Colokan adaptor


RSTGB050PLS00.3-05

Koneksi listrik

Kabel: 0.3 m, PVC; 5 x 1.5 mm² / AWG 16

Koneksi listrik - colokan

Konektor: 1 x 7/8", lurus; pengkodean: A; Bodi cetakan: plastik; Kontak: dilapisi emas

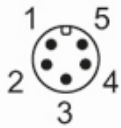

Koneksi

1	WH
2	RD
3	BU
4	OG
5	BK

	Warna core :
BK =	hitam
BU =	biru
RD =	merah
OG =	oranye
WH =	putih