


Colokan adaptor

RSTGH040ALS00.3-04

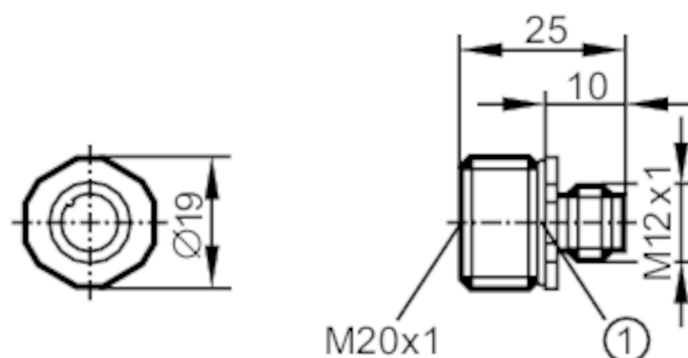

1 O-ring

Data kelistrikan

Tegangan pengoperasian [V] < 250 DC

Kondisi pengoperasian

Suhu sekitar [°C] -20...90

Data teknis

Berat [g] 22.68

Ulir pemasangan M20

Material aluminium dianodisasi 10...20 µm

Material bodi detakan aluminium, dianodisasi 10...20 µm

Keterangan

Jumlah paket 1 buah

Koneksi listrik

Kabel: 0.5 m, PVC; 4 x 0.34 mm² / AWG 22

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: aluminium, dianodisasi 10...20 µm





Colokan adaptor

RSTGH040ALS00.3-04

Koneksi

1	BN
2	WH
3	BU
4	BK

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
WH =	putih